


Studbolt with 2 heavy hexagon nuts ASME B16.5/ B18.2.2 Steel ASTM A193 - ASTM A194 Plain Gr.B7 - Gr.2H 7/8X385 (15.1/4)

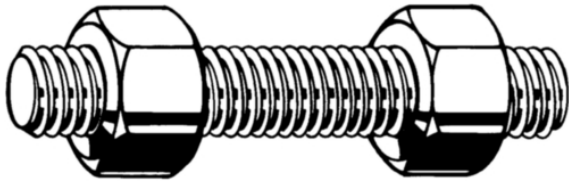

Article number	22080.222.387
Brand	-
UBB	500578026428
UNSPSC	31161619
EAN	8715494343657
PKG. of 1	Full Box Only

Technical Parameters

Diameter (inch)	7/8
Length (L) (mm)	385
Length (L) (Inch - ft)	15.1/4

Info

Tolerances of the total length of the studbolts according to ASME B16.5 Table C-3 L is the nominal length of the studbolt, measured from the first to the last full thread and thus excluding the chamfered ends.

Class	Gr.B7 - Gr.2H
Material	Steel
Material technical	ASTM A193 - ASTM A194
Thread direction	Right
Surface treatment	Plain
Thread	Unified National Coarse

Standards

BS	≈4882
ASTM	A193/A194
ASME	B16.5/B18.2.2

Technical Specification

B	1.7/16
---	--------

Technical Drawing

M 21.8
Threads per inch 9

