


Studbolt with 2 heavy hexagon nuts ASME B16.5/ B18.2.2 Steel ASTM A193 - ASTM A194 Plain Gr.B7 - Gr.2H 1 Inch X380 (15)

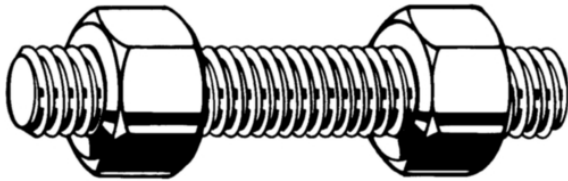

Article number	22080.254.381
Brand	-
UBB	951353844859
UNSPSC	31161619
EAN	8715493347007
PKG. of 1	Full Box Only

Technical Parameters

Diameter (inch)	1 Inch
Length (L) (mm)	380
Length (L) (Inch - ft)	15 Inch

Info

Tolerances of the total length of the studbolts according to ASME B16.5 Table C-3 L is the nominal length of the studbolt, measured from the first to the last full thread and thus excluding the chamfered ends.

Class	Gr.B7 - Gr.2H
Material	Steel
Material technical	ASTM A193 - ASTM A194
Thread direction	Right
Surface treatment	Plain
Thread	Unified National Coarse

Standards

ASTM	A193/A194
BS	≈4882
ASME	B16.5/B18.2.2

Technical Specification

B	1.5/8
---	-------

Technical Drawing

M 25
Threads per inch 8

