


Studbolt with 2 heavy hexagon nuts ASME B16.5/ B18.2.2 Steel ASTM A193 - ASTM A194 Zinc plated Gr.B7 - Gr.2H 5/8X120 (4.3/4)

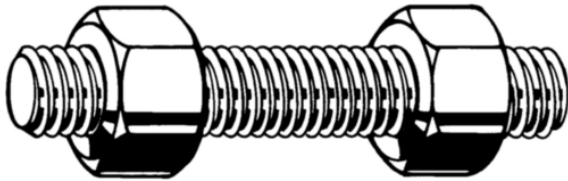

Article number	22082.158.120
Brand	-
UBB	951353664257
UNSPSC	31161619
EAN	8715493205567
PKG. of 1	Full Box Only

Technical Parameters

Diameter (inch)	5/8
Length (L) (mm)	120
Length (L) (Inch - ft)	4.3/4

Info

Tolerances of the total length of the studbolts according to ASME B16.5 Table C-3 L is the nominal length of the studbolt, measured from the first to the last full thread and thus excluding the chamfered ends.

Class	Gr.B7 - Gr.2H
Material	Steel
Material technical	ASTM A193 - ASTM A194
Thread direction	Right
Surface treatment	Zinc plated
Thread	Unified National Coarse

Standards

ASME	B16.5/B18.2.2
ASTM	A193/A194
BS	≈4882

Technical Specification

B	1.1/16
---	--------

Technical Drawing

M	15.5
Threads per inch	11

