



Bearing preload disc spring Spring steel Phosphated 51,5X35,5X0,6MM

Article number 36460.550.006

Brand -

UBB 950357490925

UNSPSC 31161811

EAN 8715492763112

PKG. of 1 Full Box Only

Technical Parameters


Diameter	35.5 mm
d _e	51.5
d _i	35.5
Material	Spring steel
Outer diameter	51.5
Surface treatment	Phosphated
Info	Warning: electroplating of these products may cause hydrogen embrittlement.F = spring load in Newton at a deflection s ≈ 0,75 h ₀ (h ₀ = l ₀ - t).Extensive technical data available on request.

Standards

Technical Specification

d _i (H12)	35.5
D (mm)	35.5
F	135
l ₀	1.5
t	1.5

Technical Drawing

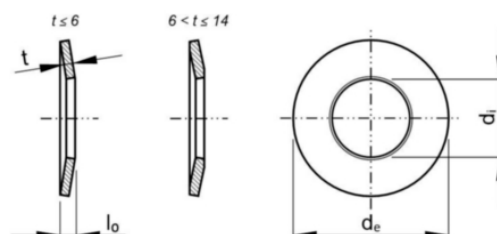

Thickness 0.6
FABORY