



Grooved pin, half length taper grooved DIN 1472 Free-cutting steel 1,5X10MM

Article number	39720.015.010
Brand	-
UBB	500645365221
UNSPSC	31163215
EAN	8717077083615
PKG. of 1	Full Box Only

Technical Parameters

Diameter	1.5 mm
Length	10 mm
Material	Free-cutting steel
Info	V = minimum shear strength double shear in kN (valid for steel pins only). Diameter d2 is the diameter over the grooved edges (valid for steel pins only). The recommended tolerance class for the accommodating hole diameter d1 (nominal) is H11. The nominal length (L, tolerance class js15) does not include the rounded ends.


Standards

NEN	≈2603
ISO	≈8745
DIN	1472

Technical Specification

c ≈	0.2
d1	1.5
d2 ≈	1.6
D (mm)	1.5
L (mm)	10

Technical Drawing

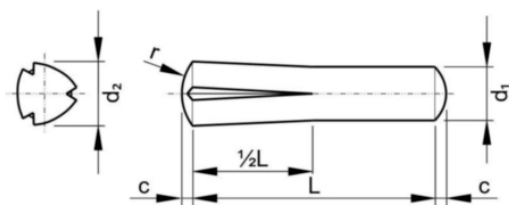

$r \approx$ 1.5

Tolerance h9

V 1.6