



Grooved pin, half length reverse DIN 1474 Free-cutting steel 5X16MM

Article number	39740.050.016
Brand	-
UBB	950359143571
UNSPSC	31163215
EAN	8715492826930
PKG. of 1	Full Box Only

Technical Parameters

Diameter	5 mm
Length	16 mm
Material	Free-cutting steel
Info	V = minimum shear strength double shear in kN (valid for steel pins only). Diameter d2 is the diameter over the grooved edges (valid for steel pins only). The recommended tolerance class for the accommodating hole diameter d1 (nominal) is H11. The nominal length (L, tolerance class js15) does not include the rounded ends.


Standards

NEN	≈2605
ISO	≈8741
DIN	1474

Technical Specification

c ≈	0.63
d1	5
d2 ≈	5.3
D (mm)	5
L (mm)	16

Technical Drawing

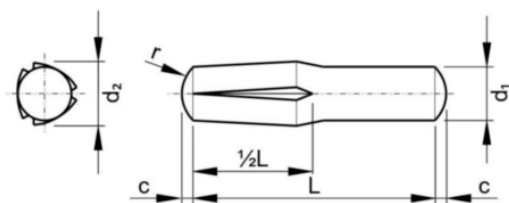

$r \approx$	5
Tolerance	h11
V	16.5