


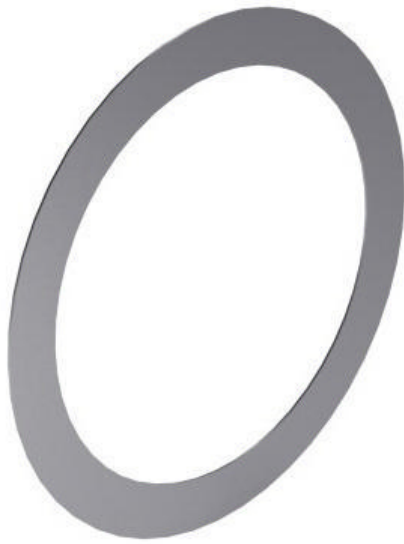

Shim ring thickness h=0,2MM DIN 988 Stainless steel A2 h=0,2MM 50X62MM

Article number	51554.500.062
Brand	-
UBB	500700889222
UNSPSC	31163301
EAN	8715492966285
PKG. of 1	Full Box Only

Technical Parameters

Diameter	50 mm
Material	Stainless steel
Material technical	A2
Outer diameter	62
Info	h=0,2MM

Standards

DIN	988
-----	-----

Technical Specification

d1	50
d1 (max.)	50.33
d1 (min.)	50.08
d2	62
d2 (max.)	61.9
d2 (min.)	61.6
D (mm)	50
Thickness	0.2

Technical Drawing

