


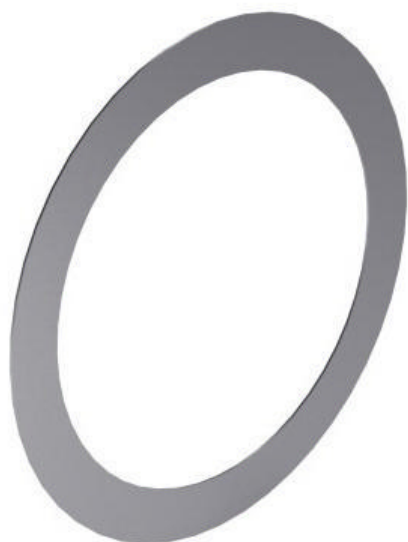

Shim ring thickness h=0,3MM DIN 988 Stainless steel A2 h=0,3MM 25X35MM

Article number	51556.250.035
Brand	-
UBB	500700891517
UNSPSC	31163301
EAN	8715492966704
PKG. of 1	Full Box Only

Technical Parameters

Diameter	25 mm
Material	Stainless steel
Material technical	A2
Outer diameter	35
Info	h=0,3MM

Standards

DIN	988
-----	-----

Technical Specification

d1	25
d1 (max.)	25.275
d1 (min.)	25.065
d2	35
d2 (max.)	34.92
d2 (min.)	34.67
D (mm)	25
Thickness	0.3

Technical Drawing

