


FISCHER Nail sleeve Steel Zinc plated FNH 6/30

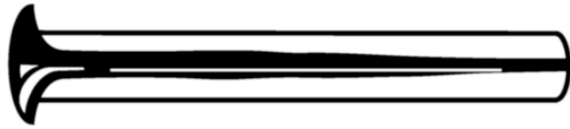

Article number	63224.060.030
Brand	-
UBB	500676091936
UNSPSC	31162103
EAN	4048962293258
PKG. of 1	Full Box Only

Technical Parameters

Diameter	6 mm
Length	30 mm
Material	Steel
Surface treatment	Zinc plated
Type no.	FNH
Info	Drill depth (min.) for through fixing. Allowable loads in kN are valid for non-structural applications. Required safety factors are taken into account.

Standards

Technical Specification

Concrete \geq C20/25	0.5
D (mm)	6
Drill depth (min.)	40
Drill \varnothing	6
Effective anchorage depth (hef)	30
L (mm)	30
Type	FNH6/30

Technical Drawing

