

FISCHER Hammerfix type N-Z Plastic Nylon (polyamide) Zinc plated N5X40MM Brown



Article number	63611.050.040
Brand	-
UBB	950372048724
UNSPSC	31162103
EAN	4006209962084
PKG. of 1	Full Box Only

Technical Parameters


Diameter	5 mm
Length	40 mm
Color	Assorted
Material	Plastic
Surface treatment	Zinc plated
Type no.	N-Z
Info	Allowable loads in kN are valid for screw nails with specified diameters. Allowable load includes the safety factor 4. With pre-assembled steel zinc plated or stainless steel A2 nail with Pozidriv (Z) cross recessed head.

Standards

Technical Specification

Brick Mz12	0.14
Cellular concrete $\geq$ PB2, PP2 (G2)	0.03
Cellular concrete $\geq$ PB4, PP4 (G4)	0.5
Concrete C20/25	0.16
D (mm)	5

Technical Drawing

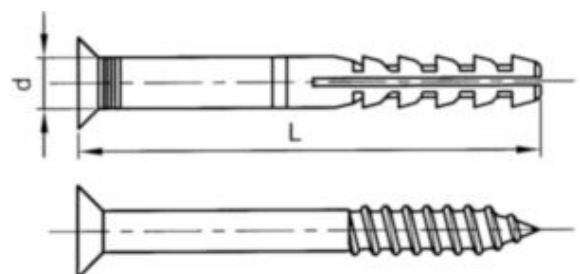

Drill depth (min.)	55
Drill ø	5
Grip range (max.)	15
L (mm)	40
Staples & Nail dimension	3.5
Pumice grit V4	0.05
Sandlime brick KS12	0.14
Type	N5X40 BR